

MICRO (M12) Cordsets


4 Pole, 22 AWG, TPE Cable

3/3

A Belden Brand


Part Number: See page 1&2

SALES / ENGINEERING DRAWING
aCATPD1605...BAB...redrawn - 10.22.08
REV A, 3.29.17, updated logos, B Baruffalo

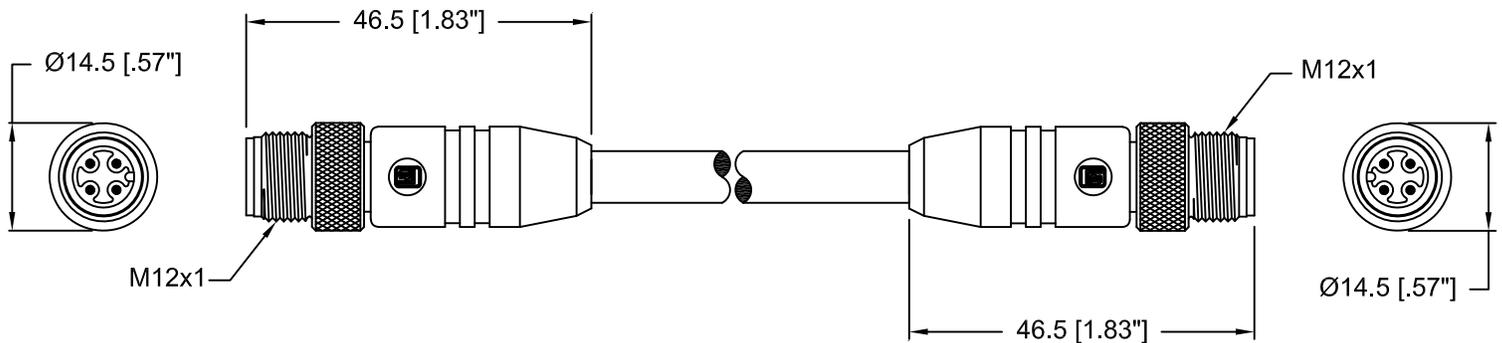


RST 4 -RST 4-643/XX

FACE VIEW MALE

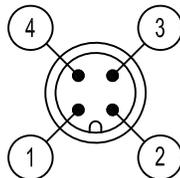

FACE VIEW FEMALE

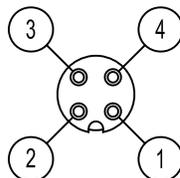

1. BROWN
2. WHITE
3. BLUE
4. BLACK

Materials:

Molded Body:	Polyurethane, yellow
Coupling Nut:	Brass, nickel plated
Contacts:	Brass, gold plated
Insert:	Polyurethane
O-ring:	Viton

Mechanical:

Temperature:	-40°C to 90°C
Protection:	IP 68, NEMA 6P

Electrical:

Current Rating:	4A
Voltage Rating:	250V

Cable Specifications:

Cable Jacket:	TPE, yellow
Overall Diameter:	.246"
Conductor:	22 AWG , stranded
UL Recognition:	AWM 20327, PLTC